



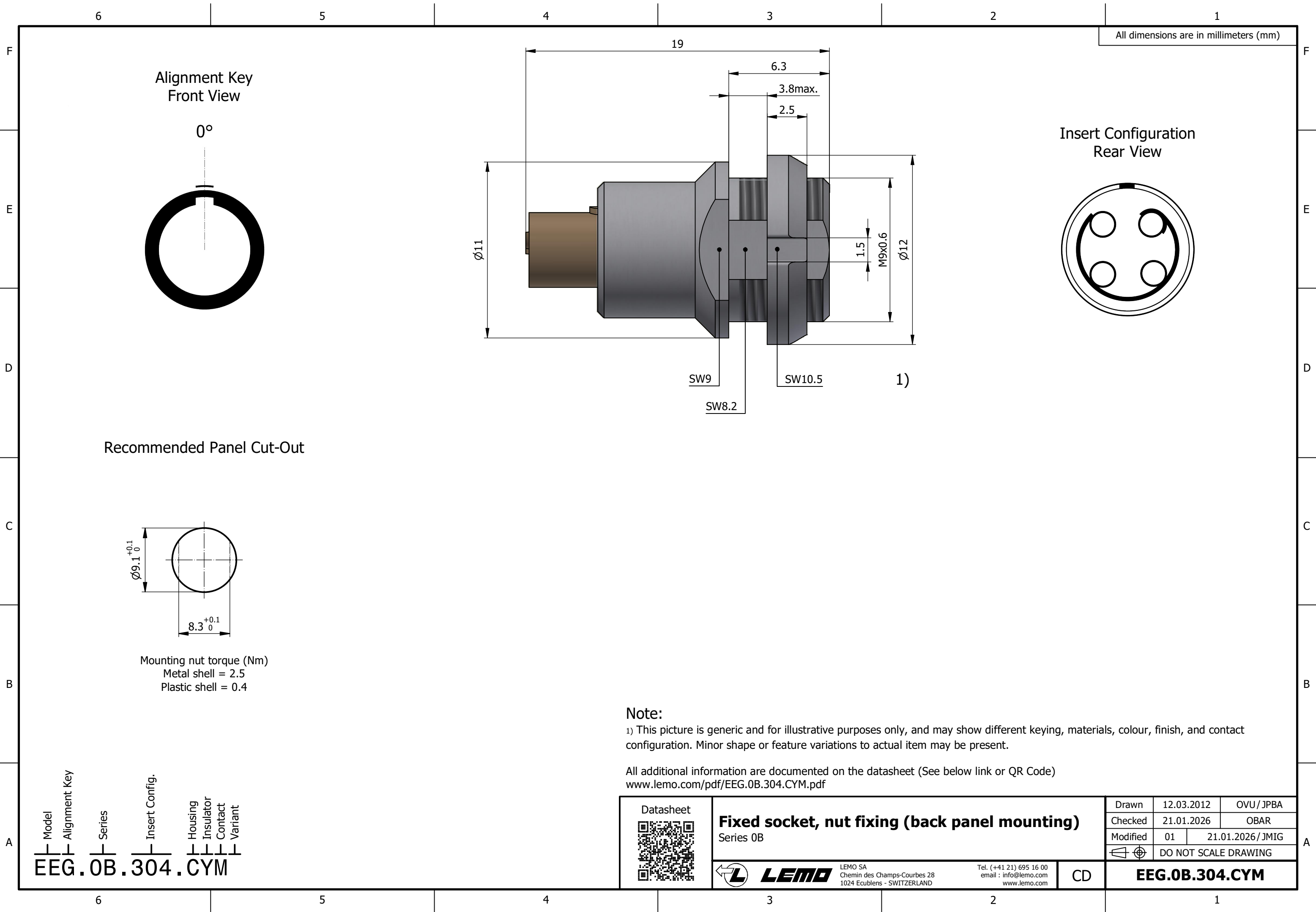

All dimensions are in millimeters (mm)

Recommended Panel Cut-Out

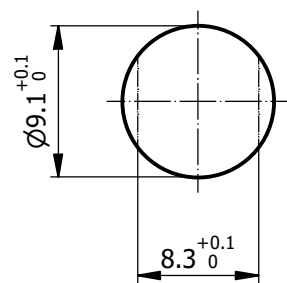

Mounting nut torque (Nm)
Metal shell = 2.5
Plastic shell = 0.4

Note:

1) This picture is generic and for illustrative purposes only, and may show different keying, materials, colour, finish, and contact configuration. Minor shape or feature variations to actual item may be present.

All additional information are documented on the datasheet (See below link or QR Code)
www.lemo.com/pdf/EEG.0B.304.CYM.pdf

Model Alignment Key Series Insert Config. Housing Insulator Contact Variant
EEG.0B.304.CYM

	Fixed socket, nut fixing (back panel mounting)		Drawn	12.03.2012	OVU / JPBA
	Series 0B		Checked	21.01.2026	OBAR
			Modified	01	21.01.2026 / JMIG
			DO NOT SCALE DRAWING		
 LEMO SA Chemin des Champs-Courbes 28 1024 Ecublens - SWITZERLAND		Tel. (+41 21) 695 16 00 email : info@lemo.com www.lemo.com		CD	
EEG.0B.304.CYM					