

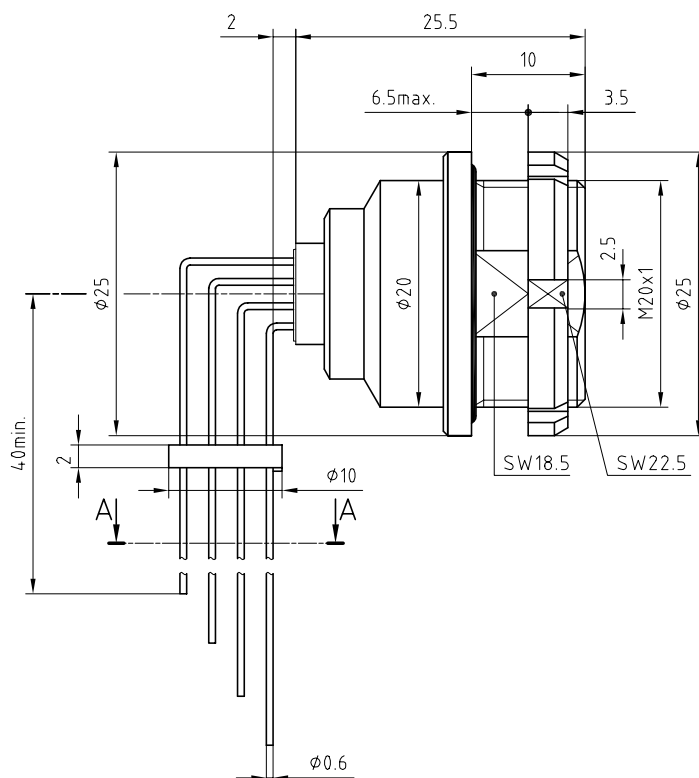


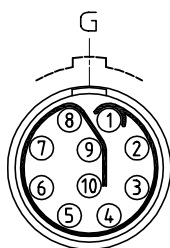


Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Earthing crown	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Insulator	: PEEK	-
Female contact	: Bronze (UNS C54400)	Gold plated (ISO 4523)
Clip	: Cu-Be (UNS C17200)	-
Notched nut	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Other metallic part	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
O-rings	: MVQ	-
Contact wire	: Bronze (UNS C27400)	Tinned
Position insert	: FEP	-

Panel cut-out

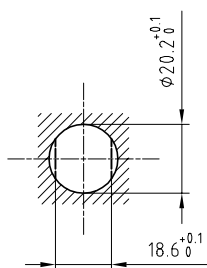

Torque for
mounting
nut : 9 Nm

A-A cross-section (PCB drilling pattern)

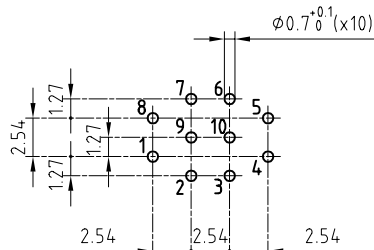

Spanner for notched nut : DCH.91.251.PA

**Fixed socket , nut fixing , with key (G) , with elbow
(90°) contact for PCB . (Back panel mounting) .
Series 2K , multipole (10)**

ETUDE N° E9600

Echelle

Dessiné

22.12.97

RM0 / RM0

Contrôle

25.08.04

RM0 / CDE

Modif.

01

25.08.04 / OVU



LEMO

CH-1024 Ecublens

EEG.2K.310.CLV