



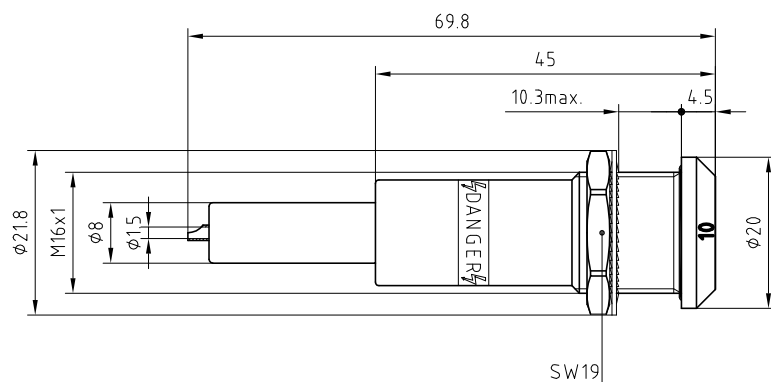

Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Earthing crown	: Cu-Be (UNS C17200)	Gold plated (ISO 4523)
Insulator	: PTFE	-
Female contact	: Cu-Be (UNS C17300)	Gold plated (ISO 4523)
Locking washer	: Bronze (UNS C52100)	Nickel plated (FS-QQ-N-290A)
Gland	: Silicone (HTV)	-
Other metallic parts	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
O-Ring	: Silicone (MVQ)	-
Label	: Polyester	Yellow

Panel cut-out

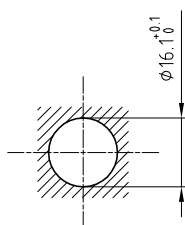

Torque for
mounting
nut : 7 Nm

Fixed socket , nut fixing .
Series 1Y , (1) HV(φ1.4)

ETUDE N° E2815

Echelle —	Dessiné	05.07.2001	OVU / RMO
	Contrôle	20.09.2013	JPBA / ATVI
	Modif.	02	20.09.2013/ OVU



LEMO

CH-1024 Ecublens

ERA.1Y.410.CTL