



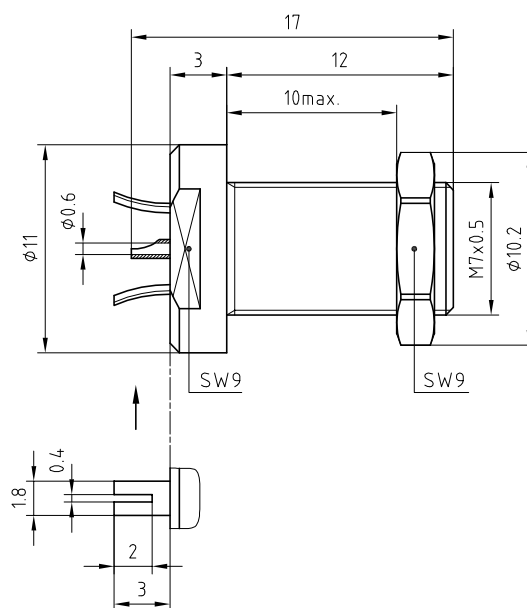

Outer shell	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Earthing crown	: Cu-Be (UNS C17300)	Gold plated (ISO 4523)
Insulator	: PTFE	-
Female contact	: Bronze (UNS C54400)	Gold plated (ISO 4523)
Hexagonal nut	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Earthing tags	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Sealing resin	: Epoxy	-
O-ring	: Viton (FPM)	-

Panel cut-out

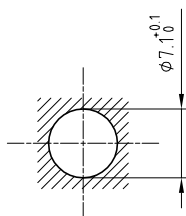

Torque for
mounting
nut : 1 Nm

Spanner for nut : DCG.91.149.0TN

**Fixed socket with earthing tags , nut fixing ,
vacuumtight . (Back panel mounting) .
Series 00 , coaxial (50Ω)**

ETUDE N° E4278-E3126

Echelle —	Dessiné	04.02.2002	BC / RMO
	Contrôle	07.06.2011	JPBA/ATVI
	Modif.	02	07.06.2011/ OVU



LEMO

CH-1024 Ecublens

EWF.00.250.NTLPV