


Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Latch sleeve	: Special brass	Nickel plated (FS-QQ-N-290A)
Collet nut	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Cap	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Elbow outlet	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Positioning pin	: Stainless steel (AISI303)	-
Insulator	: PEEK	-
Male contact	: Brass (UNS C38500)	Gold plated (ISO 4523)
Other metallic parts	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)

Stripping

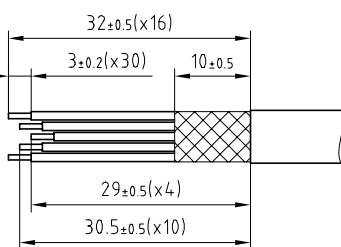

Parts that must be ordered separately :  
Flat spanners set : DCP.91.023.TN

Maximum torque mounting collet nut : 4 Nm  
Maximum torque mounting cap : 1.5 Nm

Elbow plug (90°), with key (G),  
with cable collet. Cable output on right side.  
Series 3B, multiple (30)

ETUDE N° E4195

Echelle —	Dessiné	18.12.06	OVU / RMO
	Contrôle	18.12.06	RMO / CDE
	Modif.	00	18.12.06 / OVU



**LEMO**

CH-1024 Ecublens

**FHG.3B.330.YLAD12**