

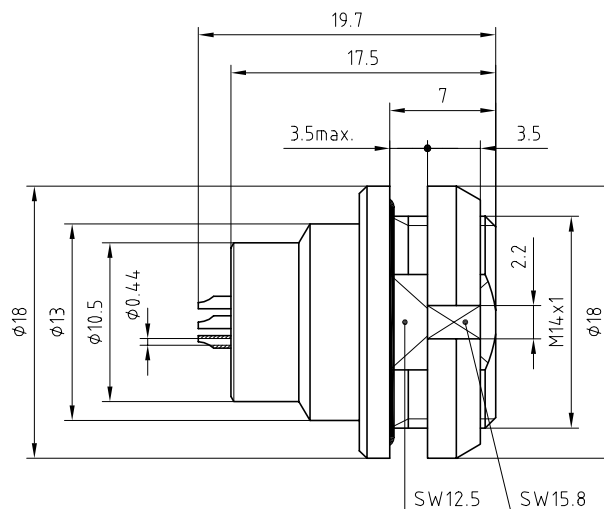


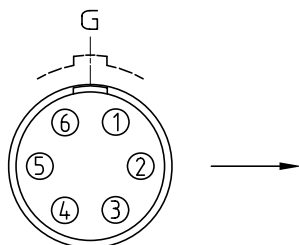

Outer shell	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Earthing crown	: Bronze (UNS C54400)	Nickel plated (FS-QQ-N-290A)
Insulator	: PEEK	-
Female contact	: Bronze (UNS C54400)	Gold plated (ISO 4523)
Notched nut	: Brass (UNS C38500)	Chrome plated (FS-QQ-C-320B)
Other metallic part	: Brass (UNS C38500)	Nickel plated (FS-QQ-N-290A)
Sealing resin	: Epoxy	-
O-rings	: Viton (FPM)	-

Panel cut-out

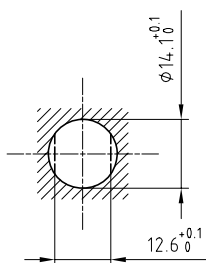

Torque for
mounting
nut : 5 Nm

Spanner for notched nut : DCH.91.181.PA

Fixed socket , nut fixing , with key (G) ,
watertight . (Back panel mounting) .
Series OK , multipole (6)

ETUDE N° E9756

Echelle —	Dessiné	01.06.06	OVU / RMO
	Contrôle	01.06.06	RMO / CDE
	Modif.	00	01.06.06 / OVU



LEMO

CH-1024 Ecublens

HEG.OK.306.CLLP